


XA RG58

RG coax cable for video use

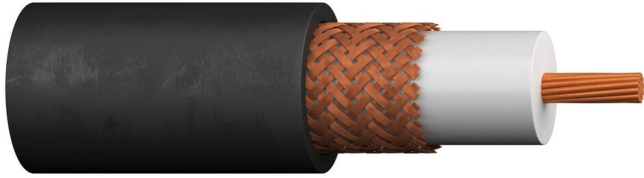

PRODUCT CONSTRUCTION:

- Conductors:** Copper per ASTM B3 · Tinned copper per ASTM B33
- Insulation/Core:** Solid and foam polyethylene (PE) · Foam fluoropolymer (FEP)
- Shield:** Tinned copper braid
- Jacket:** Premium PVC compound
- Applications:** Suitable for RF signal transmission · Broadcast · LAN & data transmission

APPLICATION PROPERTIES

Flame retardant	No	Outdoor installation	No
Halogen free	No	Underground installation	No
Resistant to UV	No		

STANDARDS AND APPROVALS



ELECTRICAL PROPERTIES

Catalog Number	AWG / Kcmil	Nom. insulation o.d. [in]	Nominal diameter over insulation [mm]	Nominal overall o.d.	Nominal outer diameter [mm]
C1166	20	0.116	2.9	0.195	4.95

We reserve the right to do changes as a result of running product development and/or changes in standards