


## RG6 COAX CABLE

RG coax cable for video use

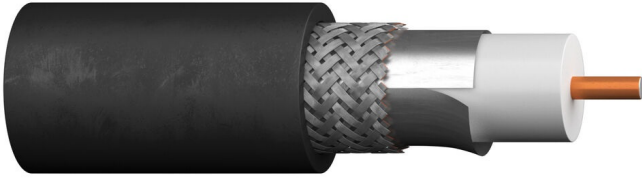

### PRODUCT CONSTRUCTION:

Conductors: Copper per ASTM B3; Copper-clad steel per ASTM B869 Insulation/Core: Foam polyethylene (PE) Shield: Bare copper or aluminum braid; Flexfoil® shield Jacket: Premium PVC compound Applications: Suitable for RF signal transmission; MATV; CATV; CCTV; HDTV; Digital video; Drop cable; FM broadcast  
Nominal Outer Diameter : 6.86 x 15.11 mm. & 0.267 x 0.595 in.

Packaging: Please contact Customer Service for packaging and color options

### APPLICATION PROPERTIES

Flame retardant	No	Resistant to UV	No
Halogen free	No	Outdoor installation	No
Low smoke	No	Underground installation	No
Oil resistant	No		

### STANDARDS AND APPROVALS



### ELECTRICAL PROPERTIES

Catalog Number	AWG / Kcmil	Nom. insulation o.d. [in]	Nominal diameter over insulation [mm]	Nominal overall o.d.	Nominal outer diameter [mm]
C5889	18	0.18	4.6	0.298	7.57
395011	18	0.18	4.6	0.275	6.91
C5804	18	0.18	4.6	0.27	6.86
C5777	18	0.18	4.6	0.271	6.88
C5785	18	0.18	4.6	0.298	7.57
C5761	18	0.18	4.6	0.275	6.98
C5822	18	0.18	4.6	0.27	6.86
C5775	18	0.18	4.6	0.276	7.01
C5886	18	0.18	4.6	0.276	7.01
C8029	18	0.18	4.6	0.275	6.99

We reserve the right to do changes as a result of running product development and/or changes in standards